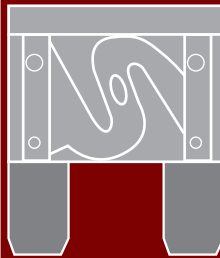
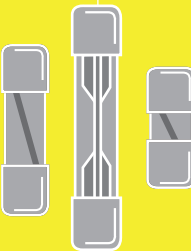
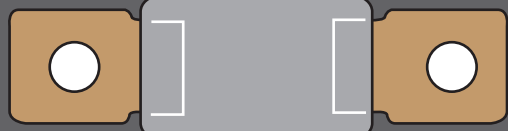


GLASS

AGC	SFE	UK
AGU	AGC	AGU
AGY	SFE14	AGW
SFE14	AGW	AGA
AGC	AGU	AGW
AGU	AGW	AGX
AGW	AGX	AGY
AGX	AGY	SFE
AGY	SFE	UK

Fuse Selection Chart

FUSE TYPE	ATO®								MINI®				MAXI		GLASS		
ACTUAL FUSE SIZE																	
PHOTO																	
Series Name	FHAC1	FHAC2	FHA1	FHA2	FHA-GLO	AFH1	AFH1	SEALED ATO	FHM1	FHM2	FHM-GLO	SEALED MINI	MAH1	FNY1	FNY2		
Holder Type	In-Line		In-Line		In-Line	In-Line Panel Mount		In-Line	In-Line		In-Line	In-Line	In-Line	In-Line	In-Line	In-Line	
Max Amperage	20A	30A	20A	30A	30A	20A	30A	30A	20A	30A	30A	30A	60A	20A	30A		
Wire Color	Black	Orange	Black	Orange	Red	Black	Red	Red	Black	Orange	Red	Red	Black or Red		Black	Orange	
Weatherproof	•	•			•			•	•	•	•	•	•		•	•	
Notes	Standard	Heavy Duty	Standard	Heavy Duty	Heavy Duty	Standard	Heavy Duty	Heavy Duty	Standard	Heavy Duty	Heavy Duty	Heavy Duty	Standard		Standard	Heavy Duty	

FUSE TYPE	JCASE® and Low Profile JCASE®						MIDI®			MEGA		
ACTUAL FUSE SIZE												
PHOTO												
Series Name	FHJC1	FHJC2	FHJ1	FHJ2	498	Compact-498	FLEX-MIDI	298	SN	FLEX-MEGA		
Holder Type	In-Line		In-Line		In-Line	In-Line	Bolt-Down	Bolt-Down	Bolt-Down	Bolt-Down		
Max Amperage	40A	60A	40A	60A	200A	200A	200A	500A	500A	500A		
Wire Color	Red	Red	Red	Red	–	–	–	–	–	–		
Weatherproof	•	•				with heat shrink			•			
Notes	Standard	Heavy Duty	Standard	Heavy Duty	Standard	Compact	Busbars Available	Standard	AssureLatch & IP69K	Busbars Available		