


# 277 IN-LINE SERIES

## 32V 20A IN-LINE BLADE FUSE HOLDER

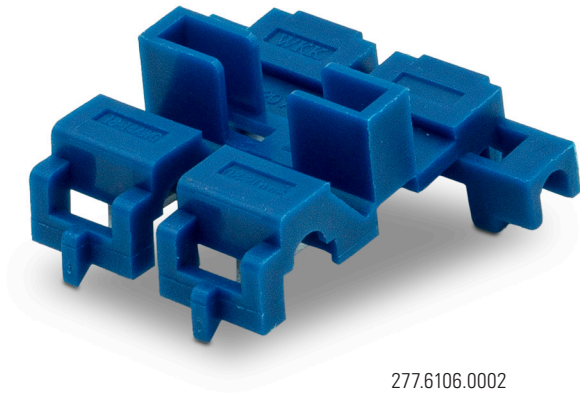

277.6106.0002

### Description

The 277 In-Line Series 32V 20A In-Line Blade Fuse Holder is available for ATO® blade fuses as well as FKS fuses and is compatible with fuses rated up to 20A (fuses sold separately). The easy-to-install in-line fuse holder handles up to 15A of continuous current. A waterproof 277 In-Line Series fuse holder model featuring red wire leads is available.

### Web Resources

Download 2D print, installation guide and technical resources at: [littelfuse.com/277InLine](https://www.littelfuse.com/277InLine)

### Specifications

<b>Current Rating Continuous:</b>	15 Amps
<b>Current Rating Max:</b>	20 Amps
<b>Fuse Type:</b>	ATO, FKS Fuses
<b>Mounting Method:</b>	In-Line Fuse Holder
<b>Max Voltage Rating:</b>	32 VDC

### Applications

- Automotive Circuit Protection
- Accessory Circuits

### Features and Benefits

- Accepts fuses rated up to 20A (fuses sold separately)
- Handles up to 15A of continuous current
- Available for ATO® blade fuses and FKS fuses
- Waterproof fuse holder model with a tetherable, sealed cover and 2.5 mm<sup>2</sup> red PVC FLY HT105° ISO 6722 wire leads is available

### Ordering Information

PART NUMBER	DESCRIPTION	CURRENT RATING MAX	FUSE TYPE	MOUNTING METHOD	MAX VOLTAGE RATING
277.6106.0002	32V 20A In-Line Blade Fuse Holder for FKS Fuses	20 Amps	FKS Fuse	In-Line Fuseholder	32VDC
277.6306.0001	32V 20A Waterproof In-Line Blade Fuse Holder for ATO® Fuses	20 Amps	ATO Fuse	In-Line Fuseholder	32VDC