

# 08010200 BATTERY DISCONNECT SWITCHES

250A • SPST • IP65 • M10 Studs • Fixed T-Handle



## Description

Manual Battery Disconnect Switch features a plastic fixed T-handle and corrosion protected aluminum body designed to be used in harsh environment. Compatible as a cross reference to competitive products in the market. 250A single pole battery switch with M10 Studs.

## Features/Benefits

- 250A continuous current rating
- Highly visible bright red T-handle
- Compatible with competitive products
- Waterproof and dustproof to IP65

## Specifications

<b>Max Operating Voltage:</b>	24V DC
<b>Max Continuous Current:</b>	250A
<b>Intermittent Current:</b>	2000A at 3 sec
<b>Operating Temp:</b>	-40°C to +80°C
<b>Ingress Protection:</b>	IP65
<b>Contacts:</b>	Silver Plated Copper
<b>Terminals:</b>	M10 (zinc-plated steel)


## Applications

- Heavy Truck
- Off-Road
- Emergency Vehicles
- Material Handling
- Mining
- Agricultural
- Marine
- Construction

## Web Resources

Download 2D prints and additional technical resources at:  
[littelfuse.com/ManualBatterySwitches](http://littelfuse.com/ManualBatterySwitches)

## Electrical Diagram

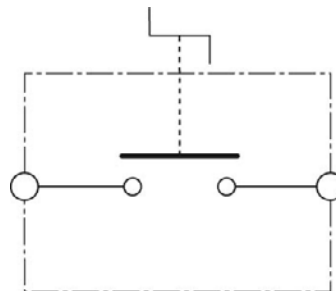

## Ordering Information

PART NUMBERS		VOLTAGE	AMPERAGE	CIRCUITRY	MOUNTING	INGRESS	NOTES
BULK	BOXED						
08010200	08010200-BX	24V DC	250A	SPST	Surface Mount	IP65	—

Dimensions in inches (millimeters)

