

# AUTO LINK PAL FUSES - 2935

RoHS



## Description


PAL fuses are commonly found on many Japanese and domestic built vehicles.

## Ratings

Part Number	Current Rating (A)	Body Color
0293525._	25	LIGHT BROWN
0293530._	30	LIGHT GREEN
0293545._	45	RED
0293565._	65	BLACK
0293575._	75	GRAY

## Dimensions (25A - 30A)

Dimensions in mm

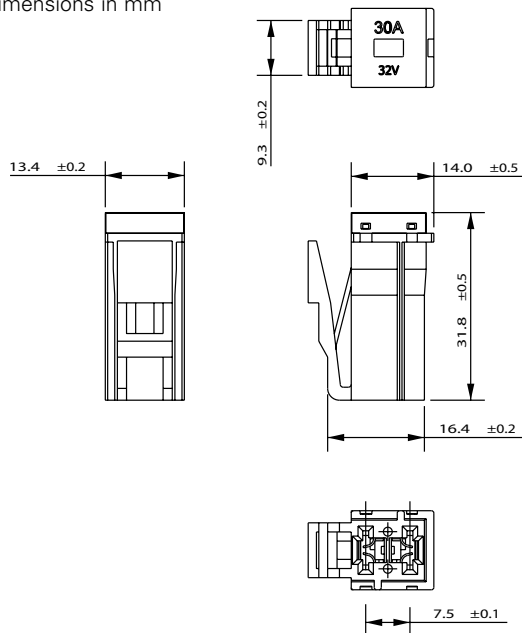

## Specifications

Voltage Rating: 32 VDC  
 Current Cycling: 24°C  
 The fuses satisfy the performance requirements after 50% of the rated current is applied for 10,000 cycles. Each cycle consists of an interrupted current with the pattern of 5 minutes ON and 10 minutes OFF.  
 Operating Temperature Range: -40°C to +125°C

Complies with JASO 0612

## Ordering Information

Part Number	Package Size
02935xx.H	100
02935xx.U	500
02935xx.MXJ	1000

## Time-Current Characteristics

% of Rating	Opening Time Min / Max (s)	
	25A - 30A	45A - 75A
110	- / -	14,400 s
150	- / -	100 s
200	5 s / 70 s	2 s / 60 s
300	- / 6 s	- / 5 s
600	- / 3 s	- / 2 s

## Dimensions (45A - 75A)

Dimensions in mm

